


# quick coupling plug KSS6-CK-9-S

Part number: 531701  
Product to be discontinued

FESTO

For self-closing safety coupling per ISO 4414, bulkhead fitting  
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

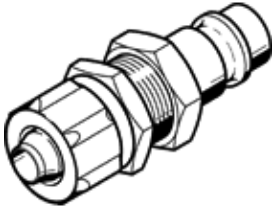

## Data sheet

Feature	Value
Nominal size	7.4 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	1,274 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Authorisation	BIA TÜV
Product weight	64 g
Pneumatic connection, port 1	CK-9
Materials note	Conforms to RoHS