 



# Branching module MS6N-FRM-1/4-Y-Z

Part number: 531974

FESTO

Includes pressure switch without indicator, direction of flow: from right to left.

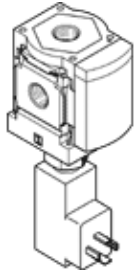

## Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 12 bar
Standard nominal flow rate in main flow direction 1->2	3,300 l/min
Standard nominal flow rate outlet at top	6,570 l/min
Standard nominal flow rate outlet at bottom	6,800 l/min
Operating medium	Compressed air
Corrosion resistance classification CRC	2
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	778 g
Pneumatic connection, port 1	NPT1/4-18
Pneumatic connection, port 2	NPT1/4-18
Pneumatic connection, port 3	NPT1/2-14
Pneumatic connection, port 4	NPT1/2-14
Materials information, housing	Aluminium die cast