


# sub-base VMPA1-IC-AP-1

Part number: 533394

FESTO

For MPA1 individual valve, internal pilot air supply.

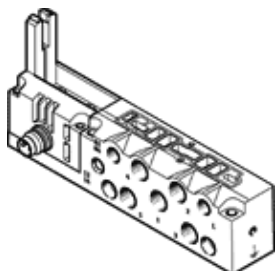

## Data sheet

Feature	Value
Width	20.2 mm
Length	107.3 mm
Grid dimension	10.5 mm
Operating pressure MPa	0.3 ... 0.8 MPa
Operating pressure	3 ... 8 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Authorisation	c UL us - Recognized (OL)
KC mark	KC-EMV
CE mark (see declaration of conformity)	to EU directive for EMC in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	92 g
Electrical connection	M8 Plug
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M7
Pneumatic connection, port 3	M7
Pneumatic connection, port 4	M7
Pneumatic connection, port 5	M7
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast