


# sub-base VMPA1-IC-AP-S-1

Part number: 533395

FESTO

For MPA1 individual valve, external pilot air supply.

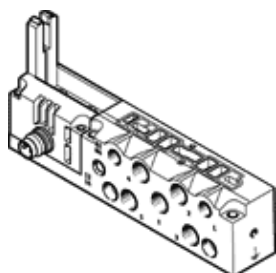

## Data sheet

| Feature                                      | Value   |
|--|---|
| Width  | 20.2 mm   |
| Length                                       | 107.3 mm  |
| Grid dimension                               | 10.5 mm   |
| Operating pressure MPa                       | -0.09 ... 1 MPa   |
| Operating pressure                           | -0.9 ... 10 bar   |
| Pilot pressure MPa                           | 0.3 ... 0.8 MPa   |
| Pilot pressure                               | 3 ... 8 bar   |
| Authorisation                                | c UL us - Recognized (OL)                                       |
| KC mark                                      | KC-EMV  |
| CE mark (see declaration of conformity)      | to EU directive for EMC<br>in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for EMC<br>To UK RoHS instructions           |
| Corrosion resistance classification CRC      | 0 - No corrosion stress   |
| PWIS conformity                              | VDMA24364-B1/B2-L   |
| Ambient temperature                          | -5 ... 50 °C  |
| Product weight                               | 92 g  |
| Electrical connection                        | M8<br>Plug  |
| Mounting method for sub-base                 | with through hole   |
| Auxiliary pilot air port 12/14               | M5  |
| Pilot exhaust port 82/84                     | M5  |
| Pneumatic connection, port 1                 | M7  |
| Pneumatic connection, port 2                 | M7  |
| Pneumatic connection, port 3                 | M7  |
| Pneumatic connection, port 4                 | M7  |
| Pneumatic connection, port 5                 | M7  |
| Materials note                               | Conforms to RoHS  |
| Material of connecting plate                 | Aluminium die cast  |