


spiral plastic tubing PUN-12X2-SG-6-BL-3/8

Part number: 533467

FESTO

Highly flexible, fibre-reinforced, hydrolysis resistant to a great extent

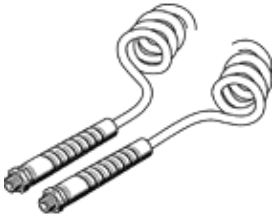

Data sheet

Feature	Value
Working length	6 m
Outside diameter	11.7 mm
Block length	1.312 m
Bending radius relevant for flow rate	65 mm
Inside diameter	7.9 mm
Coil diameter	51 mm
Number of windings	53
Temperature dependent operating pressure	-0.95 ... 13 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 60 °C
Product weight	560 g
Pneumatic connection, port 1	Male thread G3/8
Pneumatic connection, port 2	Male thread G3/8
Colour	blue
Shore hardness	A 87 +/-3
Material of connecting thread	Brass Nickel plated
Material buckling protection	POM
Material tubing	TPE-U(PU)