


silencer

U-1/8-50

Part number: 534222

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

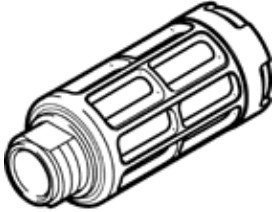

Data sheet

Feature	Value
Assembly position	Any
Container size	50
Operating pressure MPa	0 ... 1 MPa
Operating pressure	0 ... 10 bar
Flow rate to atmosphere	2,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	74 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	2.3 g
Pneumatic connection	G1/8
Material of silencer insert	PE
Materials note	Conforms to RoHS