


# Valve terminal CPA10-ASI-VI

Part number: 535847

FESTO

Grid dimension 10 mm.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

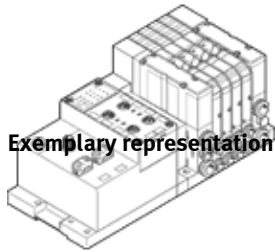

Exemplary representation

## Data sheet

~ConfIndependentDatasheet

Feature	Value
Valve function	2x3/2 open/closed, monostable 2x3/2 closed, monostable 2x3/2 open, monostable 5/2 monostable 5/2 bistable 5/3 pressurised 5/3 exhausted 5/3 closed
Standard nominal flow rate	300 l/min
Operating pressure	-0.9 ... 10 bar
Electrical connection	AS-Interface
Max. number of valve positions	8
Max. no. of pressure zones	4
Ambient temperature	-5 ... 50 °C
Width	10 mm
Protection class	IP65
Grid dimension	10 mm
Type of actuation	electrical
Valve terminal type	12
Design structure	Piston slide
Pilot air supply	external Internal
Valve terminal structure	modular and expandable
Switching position indicator	LED
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
CE mark (see declaration of conformity)	to EU directive for EMC
Corrosion resistance classification CRC	2
Medium temperature	-5 ... 50 °C