


sub-base VMPA1-FB-AP-4-1-T1

Part number: 538657

FESTO

For valve terminal MPA-S.

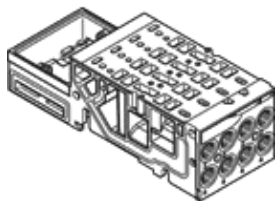

Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	185 g
Pneumatic connection, port 2	M7
Pneumatic connection, port 4	M7
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast