


# input/output module

## CP-E08-M12-CL

Part number: 538787  
Product to be discontinued

With 8 inputs

FESTO

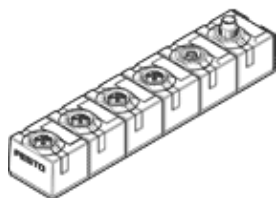

## Data sheet

Feature	Value
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
CE mark (see declaration of conformity)	to EU directive for EMC to EU directive explosion protection (ATEX) in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK EX instructions To UK RoHS instructions
KC mark	KC-EMV
Authorisation	RCM Mark c UL us - Listed (OL)
ATEX category Gas	II 3G
ATEX category Dust	II 3D
Explosion protection certification outside the EU	EPL Dc (GB) EPL Gc (GB)
Explosion ignition protection type Gas	Ex ec IIC T6 Gc X
Explosion ignition protection type Dust	Ex tc IIIC T70°C IP67 Dc X
Explosion-proof ambient temperature	-5°C ≤ Ta ≤ +50°C