


moment compensator FKC-40

Part number: 538962

FESTO

for linear drive DGC-G.

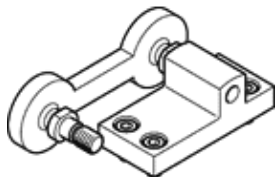

Data sheet

Feature	Value
Size	40
Radial deviation +/-	2.5 mm
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Brief maximum permitted load in force direction +/-	3,000 N
Long maximum permitted load in force direction +/-	1,400 N
Product weight	180.2 g
Materials note	Conforms to RoHS
Material joint	PA-reinforced
Material on ball stud	High alloy steel
Material plate	Wrought Aluminium alloy