 



filter silencer LFU-1/4

Part number: 539132

FESTO

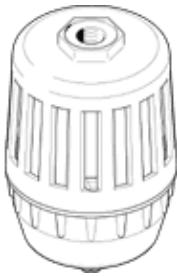

Data sheet

Feature	Value
Size	G1/4
Assembly position	Vertical +/- 5°
Grade of filtration	1 µm
Condensate drain	manual rotary
Operating pressure MPa	0 ... 1.6 MPa
Operating pressure	0 ... 16 bar 0 ... 232 psi
Flow rate to atmosphere	>= 4,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Noise reduction	Reduction by 40 dB
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	78 dB(A)
Ambient temperature	-10 ... 60 °C
Product weight	190 g
Pneumatic connection	G1/4
Material housing	PP