


# plug socket MSSD-E-M12

Part number: 539711

FESTO

For solenoid coils and valves, port pattern for JMEH, MEH and MOEH valves.

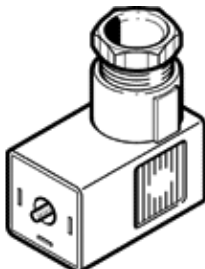

## Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	11 g
Electrical connection 1	Angled socket, square design, 3-pin, type C
Electrical connection 2	Screwed terminal
Operating voltage range DC	0 ... 300 V
Operating voltage range AC	0 ... 250 V
Acceptable current load at 40°C	6 A
Cable gland connection	M12
Permissible cable diameter	4 ... 6 mm
Terminal cross-section	0.75 mm <sup>2</sup>
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 115 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	PA-reinforced
Housing colour	Black
Material seals	HNBR