


# vertical pressure supply plate

## VABF-S4-1-P1A3-N14

Part number: 540172

FESTO

For valve terminals VTSA and VTSA-F, standard port pattern to 15407-2, for mounting between manifold sub-base and valve.

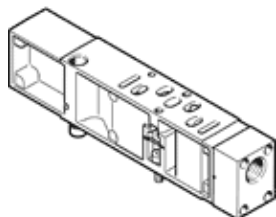

## Data sheet

Feature	Value
Width	26 mm
Based on the standard	ISO 15407-2
Assembly position	Any
Operating pressure MPa	1 MPa
Operating pressure	10 bar
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Ambient temperature	-5 ... 50 °C
Product weight	191 g
Vertical stacking type of mounting	on manifold block on individual sub-base
Pneumatic connection, port 1	1/4 NPT
Material housing	Aluminium die cast