

 

ball valve actuator unit

VZPR-BPD-22-R34

Part number: 540513

FESTO

Brass, with double-acting actuator DAPS 2/2-way, nominal width 3/4",
PN40, thread EN 10226-1.

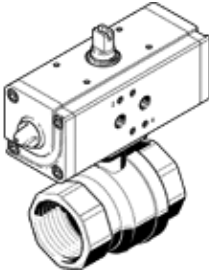

Data sheet

Feature	Value
Design structure	2-way ball valve Swivel drive
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	CNOMO with internal (female) thread
Process valve connection	Rp3/4
Switching position indicator	Knob direction = Flow direction
Nominal diameter DN	20
Operating pressure, ball valve drive	1 ... 8.4 bar
Nominal pressure of process valve	40
Medium temperature	-20 ... 150 °C
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364 zone III
Product weight	1,500 g
Corrosion resistance classification CRC	1 - Low corrosion stress