

 

# ball valve actuator unit

## VZPR-BPD-22-R1

Part number: 540514

FESTO

Brass, with double-acting actuator DAPS 2/2-way, nominal width 1",  
PN40, thread EN 10226-1.

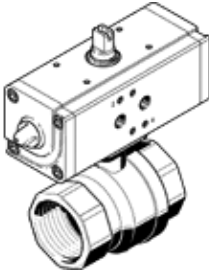

## Data sheet

Feature	Value
Design structure	2-way ball valve Swivel drive
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	CNOMO with internal (female) thread
Process valve connection	Rp1
Switching position indicator	Knob direction = Flow direction
Nominal diameter DN	25
Operating pressure, ball valve drive	1 ... 8.4 bar
Nominal pressure of process valve	40
Medium temperature	-20 ... 150 °C
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364 zone III
Product weight	1,800 g
Corrosion resistance classification CRC	1 - Low corrosion stress