


# ball valve actuator unit

## VZPR-BPD-22-R2

Part number: 540517

FESTO

Brass, with double-acting actuator DAPS 2/2-way, nominal width 2",  
PN25, thread EN 10226-1.

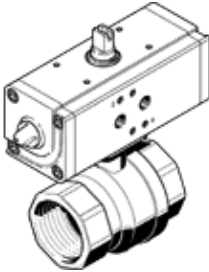

### Data sheet

Feature	Value
Design structure	2-way ball valve Swivel drive
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	CNOMO with internal (female) thread
Process valve connection	Rp2
Switching position indicator	Knob direction = Flow direction
Nominal diameter DN	50
Operating pressure, ball valve drive	1 ... 8.4 bar
Nominal pressure of process valve	25
Medium temperature	-20 ... 150 °C
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364 zone III
Product weight	5,400 g
Corrosion resistance classification CRC	1 - Low corrosion stress