


supply plate VMPA-FB-SP-V

Part number: 541082

FESTO

For valve terminal MPA-S.

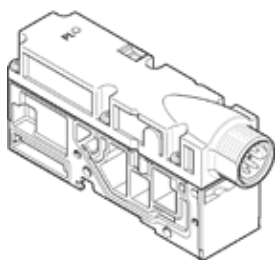

Data sheet

| Feature | Value |
|---|---------------------------|
| Nominal operating voltage DC | 24 V |
| Permissible voltage fluctuation | +/- 25 % |
| Authorisation | c UL us - Recognized (OL) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP65 |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 200 g |
| Electrical connection | 3-pin M18 |
| Materials note | Conforms to RoHS |
| Material cover | PA-reinforced |
| Material housing | Aluminium die cast |