 



push-in T-connector NEDU-M8D3-M12T4

Part number: 541597

FESTO

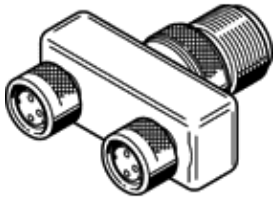

Data sheet

Feature	Value
Assembly position	Any
Connection frequency	500
Operating voltage range AC	60 V
Operating voltage range DC	60 V
Nominal operating voltage, AC	60 V
Nominal operating voltage DC	60 V
Permissible current load	4 A
Corrosion resistance classification CRC	2
Storage temperature	-25 ... 85 °C
Protection class	IP65 IP67
Ambient temperature	-25 ... 85 °C
Max. tightening torque	0.3 Nm at M8 0.5 Nm at M12
Product weight	16.9 g
Electrical connection	to EN 60947-5-2 Plug/socket M12x1 / M8x1 4-pin / 3-pin
Mounting type	Threaded
Housing colour	Black
Materials information for locknut	Brass Chromed-plated Nickel plated
Materials note	Free of copper and PTFE
Materials information, housing	TPE-U (PU), amplified
Material information for crimp connectors	Brass Gold plated