 



branching module MS12N-FRM-G

Part number: 541682

FESTO

To distribute compressed air without non-return function.

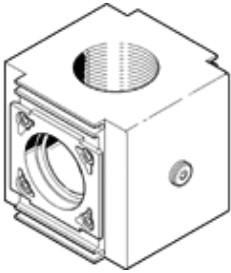

Data sheet

| Feature | Value |
|--|---|
| Assembly position | Any |
| Design structure | Branching module |
| Operating pressure | 0 ... 20 bar |
| Standard nominal flow rate in main flow direction 1->2 | 25,000 ... 42,000 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-::-] |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -10 ... 60 °C |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 3,000 g |
| Pneumatic connection, port 1 | Manifold module |
| Pneumatic connection, port 2 | Manifold module |
| Pneumatic connection, port 3 | 2 NPT |
| Pneumatic connection, port 4 | 1 NPT |
| Material housing | Aluminium die cast |