


intermediate position module

DADM-DGC-40-A

Part number: 541702

FESTO

suitable for linear drive DGC.

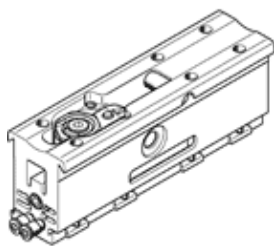

Data sheet

Feature	Value
Size	40
Assembly position	Any
Position detection	For proximity sensor
Operating pressure MPa	0.25 ... 0.8 MPa
Operating pressure	2.5 ... 8 bar 36.25 ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	300 ms
Repetition accuracy	0.02 mm
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	970 g
Mounting type	Clamped to cylinder DGC
Pneumatic connection	M5
Materials note	Conforms to RoHS
Material stop screw	Steel Galvanised
Material seals	TPE-U(PU)
Material housing	Wrought Aluminium alloy Anodised
Material lever	High alloy steel, non-corrosive
Material clip	High alloy steel, non-corrosive
Material nut	Steel Galvanised
Precision adjustment	4 mm
Mode of operation	double-acting