


# plug NECU-M-S-D12G4-C2-ET

Part number: 543109

FESTO

for modular electrical terminal CPX.

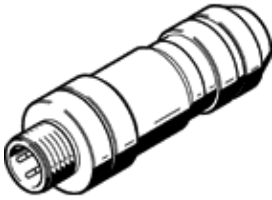

## Data sheet

Feature	Value
Based on the standard	EN 61076-2-101 EN 61984
Product weight	44.3 g
Electrical connection 1	Straight plug, M12x1, 4-pin, D-coded, screenable
Plug coding	D
Electrical connection 2	Screw terminal, can be screened
Operating voltage range DC	0 ... 250 V
Operating voltage range AC	0 ... 250 V
Surge strength	2.5 kV
Transmission properties	DIN EN 50173 / CAT 5
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	0.14 ... 0.75 mm <sup>2</sup>
Protection class	IP67
Ambient temperature	-25 ... 85 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Nickel-plated die-cast zinc
Material electrical contact	Brass, gold-plated