


# Parallel kit EAMM-U-D40-42C

Part number: 543160

FESTO

Suitable for electric drives.

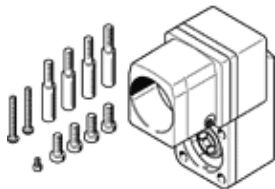

## Data sheet

Feature	Value
Size	40
Assembly position	Any
Max. speed	5,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	10.016 kgmm <sup>2</sup>
No-load driving torque	0.1 Nm
Transferable torque	3 Nm
Product weight	690 g
Materials note	Contains PWIS substances