


# axial kit EAMM-A-D60-70A

Part number: 543161

FESTO

Suitable for electric drives.

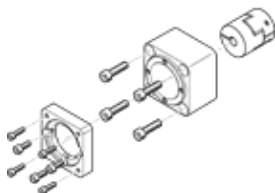

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	17 Nm
Product weight	750 g
Interface code, actuator	D60A D60B D60C
Interface code, motor in	70A
Materials note	Conforms to RoHS