


Parallel kit EAMM-U-D60-70A

Part number: 543165

FESTO

Suitable for electric drives.

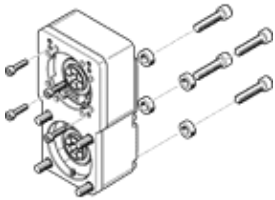

Data sheet

Feature	Value
Size	63
Assembly position	Any
Max. speed	4,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	70.5 kgmm ²
No-load driving torque	0.3 Nm
Transferable torque	5.5 Nm
Product weight	1,170 g
Materials note	Contains PWIS substances