


Parallel kit EAMM-U-D60-52C

Part number: 543168

FESTO

Suitable for electric drives.

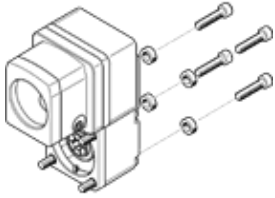

Data sheet

| Feature | Value |
|------------------------|--------------------------|
| Size | 63 |
| Assembly position | Any |
| Max. speed | 4,000 1/min |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | 0 ... 50 °C |
| Mass moment of inertia | 70.5 kgmm ² |
| No-load driving torque | 0.3 Nm |
| Transferable torque | 5.5 Nm |
| Product weight | 1,630 g |
| Materials note | Contains PWIS substances |