


# coupling

## EAMC-42-50-11-12

Part number: 543424

FESTO

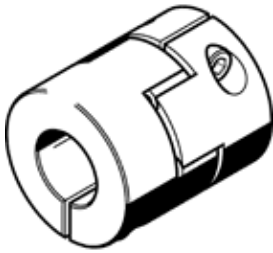

### Data sheet

Feature	Value
Holder diameter 1	11 mm
Holder diameter 2	12 mm
Size	42
Nominal length	50 mm
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	34.8 kgmm <sup>2</sup>
Transferable torque	17 Nm
Product weight	138 g
Materials note	Conforms to RoHS