 



push-in T-connector NEDU-M8D3-M8T4

Part number: 544391

FESTO

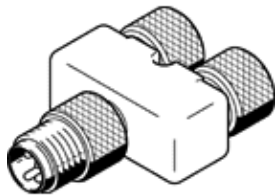

Data sheet

Feature	Value
Assembly position	Any
Connection frequency	100
Operating voltage range AC	32 V
Operating voltage range DC	32 V
Nominal operating voltage, AC	32 V
Nominal operating voltage DC	32 V
Permissible current load	2 A
Corrosion resistance classification CRC	2
Storage temperature	-25 ... 85 °C
Protection class	IP65 IP67
Ambient temperature	-25 ... 85 °C
Max. tightening torque	0.3 Nm
Product weight	9.5 g
Electrical connection	to EN 60947-5-2 Plug/socket M8x1 / M8x1 4-pin / 3-pin
Mounting type	Threaded
Housing colour	Black
Materials information for locknut	Brass Chromed-plated Nickel plated
Materials note	Free of copper and PTFE
Materials information, housing	PA
Material information for crimp connectors	Brass Gold plated