


# manifold rail

## VABM-B6-E-G14-7

Part number: 545817

FESTO

For VUVB solenoid valves.

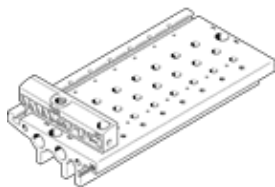

## Data sheet

| Feature                                 | Value                                       |
|---|---|
| Grid dimension                          | 21 mm                                       |
| Max. number of valve positions          | 7   |
| Corrosion resistance classification CRC | 2   |
| Max. tightening torque, H-rail mounting | 1.5 Nm                                      |
| Max. tightening torque, valve mounting  | 2 Nm  |
| Max. tightening torque, wall mounting   | 5 Nm  |
| Product weight                          | 600 g                                       |
| Auxiliary pilot air port 12/14          | G1/8  |
| Pneumatic connection, port 1            | G1/4  |
| Pneumatic connection, port 3            | G1/4  |
| Materials note                          | Free of copper and PTFE<br>Conforms to RoHS |
| Material information, manifold strip    | Wrought Aluminium alloy                     |