


manifold rail

VABM-B6-E-G12-7

Part number: 545822

FESTO

For VUVB solenoid valves.

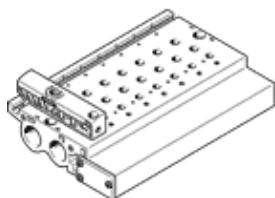

Data sheet

Feature	Value
Grid dimension	21 mm
Max. number of valve positions	7
Corrosion resistance classification CRC	2
Max. tightening torque, H-rail mounting	1.5 Nm
Max. tightening torque, valve mounting	2 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,030 g
Auxiliary pilot air port 12/14	G1/8
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 3	G1/2
Materials note	Free of copper and PTFE Conforms to RoHS
Material information, manifold strip	Wrought Aluminium alloy