


distributor FCK-3-PK-6-N

Part number: 546067

FESTO

[Metal version.](#)

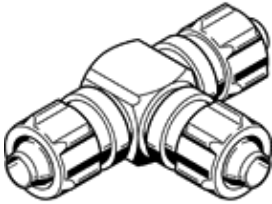

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 4.5 mm |
| Assembly position | Any |
| Operating pressure complete temperature range | 0 ... 10 bar |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 14 g |
| Pneumatic connection, port 1 | for barbed connector internal diameter 6 mm with nut |
| Pneumatic connection, port 2 | for barbed connector internal diameter 3 mm with nut |
| Material housing | Wrought Aluminium alloy |