


adapter AD-1NPT-G1-I

Part number: 546547

FESTO

Female thread one side, male thread on the other.

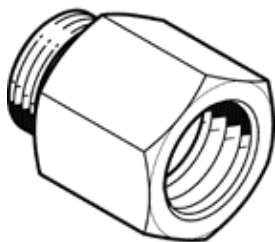

Data sheet

Feature	Value
Nominal size	24.2 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	35 Nm
Max. tightening torque, pneumatic connection 2	90 Nm
Product weight	218.86 g
Pneumatic connection, port 1	Male thread, 1 NPT
Pneumatic connection, port 2	Female thread G1
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized