


# sub-base VABS-S2-1S-G38-B-C1

Part number: 546762

FESTO

With port pattern as per ISO5599/-2.

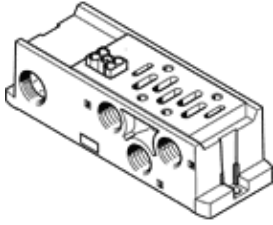

## Data sheet

Feature	Value
Width	42 mm
Based on the standard	ISO 5599-2
Assembly position	Any
Pilot air supply	Internal
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Operating voltage range AC	110 V
Operating voltage range DC	24 V
Surge strength	4 kV
Acceptable current load at 40°C	2 A
Degree of contamination	3
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4 in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	371 g
Terminal cross-section	0.08 ... 0.75 mm <sup>2</sup>
Mounting type	with through hole
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast