


vacuum filter

VAF-DB-1/4

Part number: 547261

FESTO

for filtering dirt particles

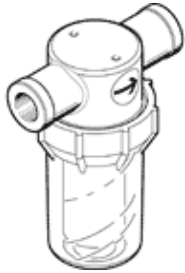

Data sheet

Feature	Value
Assembly position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 ... 0 bar
Note on operating pressure	Only for application in open vacuum systems
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364 zone III
Ambient temperature	-5 ... 50 °C
Max. tightening torque	8.7 Nm
Product weight	71 g
Mounting type	Line installation with wall/surface fixing
Pneumatic connection	G1/4
Vacuum connection	G1/4
Materials note	Conforms to RoHS
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Ejector pulse suitability	≤ 7 bar