 



vacuum generator cartridge VN-07-L

Part number: 547696

FESTO

For VN vacuum generators, high suction rate.

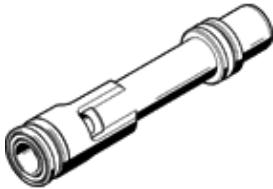

Data sheet

Feature	Value
Nominal size, Laval nozzle	0.7 mm
Assembly position	Any
Ejector characteristic	Standard High suction volume
Operating pressure	1 ... 8 bar
Nominal operating pressure	6 bar
Max. suction rate with respect to atmosphere	30.9 l/min
Air supply time at nominal operating pressure	0.82 s
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	0 ... 60 °C
Ambient temperature	0 ... 60 °C
Product weight	1.65 g
Material seals	NBR
Material receiver nozzle	POM
Material transmitter nozzle	Wrought Aluminium alloy