 



vacuum generator cartridge VN-10-L

Part number: 547698

FESTO

For VN vacuum generators, high suction rate.

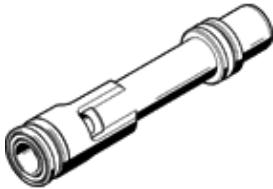

Data sheet

| Feature | Value |
|---|--|
| Nominal size, Laval nozzle | 0.95 mm |
| Assembly position | Any |
| Ejector characteristic | Standard High suction volume |
| Operating pressure | 1 ... 8 bar |
| Nominal operating pressure | 6 bar |
| Max. suction rate with respect to atmosphere | 41.5 l/min |
| Air supply time at nominal operating pressure | 0.66 s |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation not possible |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | 0 ... 60 °C |
| Ambient temperature | 0 ... 60 °C |
| Product weight | 1.65 g |
| Material seals | NBR |
| Material receiver nozzle | POM |
| Material transmitter nozzle | Wrought Aluminium alloy |