


Y-fitting NPFB-Y-R18-2G18-MFF

Part number: 547740

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminium AL 99.5 can also be used.

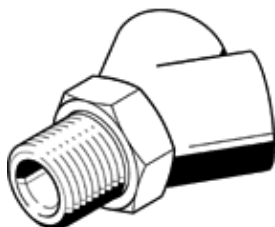

Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Operating pressure	-0.95 ... 40 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:]
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	22 g
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS