


# X-fitting NPFB-X-4G12-F

Part number: 547782

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminium AL 99.5 can also be used.

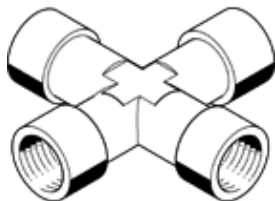

## Data sheet

| Feature                                   | Value   |
|---|---|
| Material information for threaded fitting | Brass<br>Nickel plated                                  |
| Container size                            | 10  |
| Operating pressure                        | -0.95 ... 40 bar  |
| Operating medium                          | Compressed air in accordance with ISO8573-1:2010 [-:~:] |
| Corrosion resistance classification CRC   | 1   |
| Ambient temperature                       | -20 ... 150 °C  |
| Product weight                            | 186 g   |
| Pneumatic connection, port 1              | G1/2  |
| Materials note                            | Conforms to RoHS  |