

# X-fitting


## NPFB-X-R18-3G18-MFFF

Part number: 547783

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminium AL 99.5 can also be used.

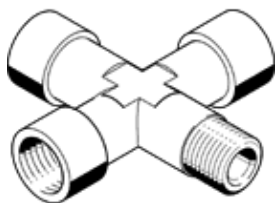

### Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Operating pressure	-0.95 ... 40 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:]
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	52 g
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS