


connecting cable SBOA-K20CP-WS

Part number: 548823

FESTO

For SBOI-Q-... and SBOC-Q-... compact vision systems

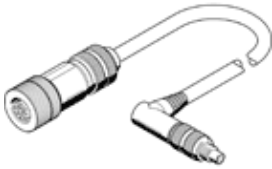

Data sheet

Feature	Value
Assembly position	Any
Cable attribute	Suitable for chain link trunking
Operating voltage range DC	≤ 60 V
Protection class	IP65 IP67 to IEC 60529
Ambient temperature with flexible cable installation	-5 ... 80 °C
Ambient temperature	-20 ... 80 °C
Electrical connection	Angled plug / straight socket
Cable structure	2x0,24+2x0,34+0,49
Cable diameter	5.5 mm
Cable length	2 m
Mounting type	With sleeve nut
Cable sheath colour	light grey
Materials note	Conforms to RoHS
Materials information, housing	Brass PUR Nickel plated
Materials information, cable sheaths	PUR
Material information for crimp connectors	bronze / brass Gold plated