

solenoid coil


MD-2-24VDC-PA

Part number: 549903

★ Core product range

For DC voltage, without plug socket.

FESTO

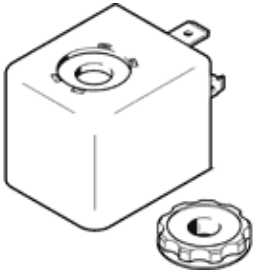

Data sheet

Feature	Value
Assembly position	Any
Duty cycle	100 %
Characteristic coil data	24 V DC: 6.8 W
Permissible voltage fluctuation	+/- 10 %
PWIS conformity	VDMA24364-B2-L
Protection class	IP65
Ambient temperature	-20 ... 50 °C
Max. tightening torque for fitting	0.5 Nm
Product weight	110 g
Electrical connection	Per DIN EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper