


solenoid coil MH-2-24VDC-PA

Part number: 549906

FESTO

For DC voltage, without plug socket.

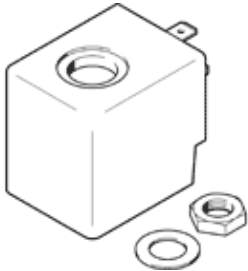

Data sheet

Feature	Value
Assembly position	Any
Switching position indicator	No
Min. pickup time	12 ms
Duty cycle	100 %
Power factor cos {phi}	0.7
Characteristic coil data	24 V DC: 7.9 W
Permissible frequency fluctuation	+/- 10 %
Permissible voltage fluctuation	+/- 10 %
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Note on degree of protection	IP00 without connector socket
Ambient temperature	-20 ... 50 °C
Max. tightening torque for fitting	2 Nm
Product weight	150 g
Electrical connection	Per DIN EN 175301-803
Mounting type	with lock nut
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper