


solenoid coil

MH-2-230VAC-PA

Part number: 549908

FESTO

For AC voltage, without plug socket.

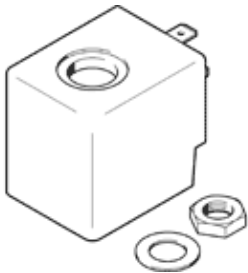

Data sheet

Feature	Value
Assembly position	Any
Switching position indicator	No
Min. pickup time	12 ms
Duty cycle	100 %
Power factor cos {phi}	0.7
Characteristic coil data	230 V AC: 14 VA
Permissible frequency fluctuation	+/- 10 %
Permissible voltage fluctuation	+/- 10 %
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Note on degree of protection	IP00 without connector socket
Ambient temperature	-20 ... 50 °C
Max. tightening torque for fitting	2 Nm
Product weight	150 g
Electrical connection	Per DIN EN 175301-803
Mounting type	with lock nut
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper