

 

plug socket MSSD-N

Part number: 550067

★ Core product range

For MD-2/2-... and MH-2/2-... solenoid coils

FESTO

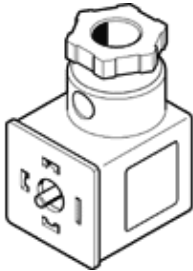

Data sheet

| Feature | Value |
|--|---|
| Based on the standard | EN 175301-803 |
| Cable outlet | Angled |
| Product weight | 30 g |
| Electrical connection 1, design | Angular |
| Electrical connection 1, connection type | Plug socket |
| Electrical connection 1, connection technology | Plug pattern type A to EN 175301-803 |
| Electrical connection 1, number of pins/wires | 3 |
| Electrical connection 1, type of mounting | On solenoid valve with M3 central screw |
| Electrical connection 2, connection technology | Screwed terminal |
| Operating voltage range DC | 0 ... 24 V |
| Operating voltage range AC | 0 ... 250 V |
| Acceptable current load at 40°C | 16 A |
| Cable gland connection | M20x1,5 |
| Cable diameter | 8 ... 10 mm |
| Nominal conductor cross-section | 1.5 mm ² |
| Protection class | IP65 |
| Note on degree of protection | in assembled condition |
| Ambient temperature | -25 ... 80 °C |
| PWIS conformity | VDMA24364 zone III |
| Materials note | Conforms to RoHS |
| Material housing | PA-reinforced |
| Housing colour | Black |
| Material screws | Steel |
| Material seals | VMQ |