


Ball valve with drive unit VZPR-BPD-22-R3R

Part number: 550336

FESTO

Comprising pneumatic DAPS semi-rotary drive, combined with a 2/2-way VAPB ball valve in stainless steel version.

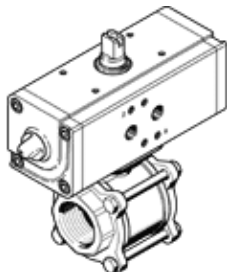

Data sheet

Feature	Value
Design structure	2-way ball valve Swivel drive
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	Line installation
Process valve connection	Rp3
Switching position indicator	Slot direction = flow direction
Nominal diameter DN	80
Operating pressure	5 ... 8.4 bar
Operating pressure, ball valve drive	1 ... 8.4 bar
Nominal pressure of process valve	63
Medium	Compressed air in accordance with ISO8573-1:2010 [-:--:] Inert gases Water Neutral fluids
Medium temperature	-10 ... 200 °C
Ambient temperature	-20 ... 80 °C
Materials note	Contains PWIS substances
Food-industry approval	No
Product weight	18,100 g
Corrosion resistance classification CRC	3