


# plug socket with cable KMYZ-4-2,5-B-EX

Part number: 550481

FESTO

Combination of MSZB and MSZC connection.

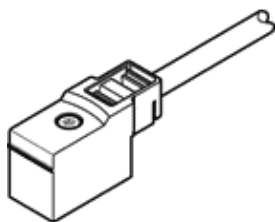

## Data sheet

Feature	Value
Maritime classification	see certificate
Mounting type	On solenoid valve with M2 central screw
Assembly position	Any
Product weight	34.5 g
Electrical connection	Plug socket angled Cable Rectangular design, MSZB
Operating voltage range DC	3 ... 36 V
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	1 A
Surge strength	900 V
Protective earth connection	Not available
Cable length	2.5 m
Cable attribute	Standard
Cable structure	2x0,35
Protection class	IP40
Ambient temperature	-10 ... 50 °C
CE mark (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA
Material electrical contact	Bronze