


# Coupling KSE-40-66-D08-D11

Part number: 550997

FESTO

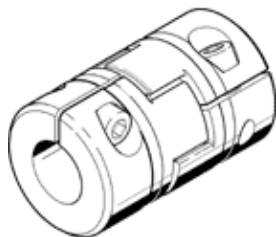

## Data sheet

Feature	Value
Holder diameter 1	8 mm
Holder diameter 2	11 mm
Size	40
Assembly position	Any
Max. speed	6,500 1/min
Mass moment of inertia	42.3 kgmm <sup>2</sup>
Transferable torque	17 Nm
Product weight	139 g
Materials note	Conforms to RoHS