


**coupling**  
**EAMC-40-66-11-15**  
Part number: 550998

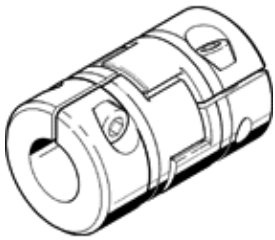

**Data sheet**

Feature	Value
Holder diameter 1	11 mm
Holder diameter 2	15 mm
Size	40
Nominal length	66 mm
Assembly position	Any
Max. speed	6,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	42.3 kgmm <sup>2</sup>
Transferable torque	21 Nm
Product weight	139 g
Materials note	Conforms to RoHS