


Connecting cable NEBV-H1G2-P-2.5-LE2

Part number: 552003

FESTO

für Magnetventile MH1, mit LED.

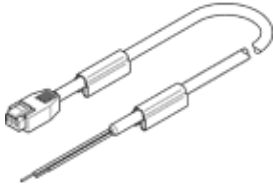

Data sheet

Feature	Value
Assembly position	Any
Cable attribute	Für statische Anwendungen
Polarity protected	for all electrical connections
Operating voltage range AC	0 ... 30 V
Operating voltage range DC	0 ... 30 V
maximum output current	2,000 mA
Stoßspannungsfestigkeit	0.8 kV
Corrosion resistance classification CRC	4
Protection class	IP40
Ambient temperature	-5 ... 70 °C -20 ... 70 °C
Product weight	60 g
Electrical connection	2-core Straight socket / cable
Cable length	2.5 m
Mounting type	Clip
Colour code, core insulation	Pin 1 = black Pin 3 = schwarz/rot
Materials note	Free of copper and PTFE
Materials information, housing	POM PUR
Materials information, cable sheaths	PVC