 



roller lever valve

RWB-3-1/8

Part number: 552432

FESTO

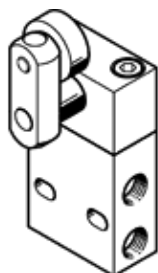

Data sheet

Feature	Value
Valve function	3/2 closed, monostable
Type of actuation	mechanical
Standard nominal flow rate	120 l/min
Operating pressure	3.5 ... 8 bar
Design structure	Piston seat
Nominal size	3.5 mm
Type of piloting	Piloted
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Actuating force	3.1 N
Product weight	160 g
Mounting type	with through hole
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 3	G1/8
Material seals	NBR
Material housing	Wrought Aluminium alloy Anodised