


plastic tubing PAN-VO-4X0.75-BL

Part number: 552439

FESTO

Flame retardant

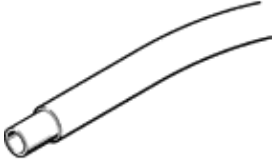

Data sheet

Feature	Value
Outside diameter	6 mm
Outside diameter for push-fit fitting	4 mm
Bending radius relevant for flow rate	20 mm
Inside diameter	2.6 mm
Min. bending radius	5 mm
Temperature dependent operating pressure	-0.95 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water Mineral oil
Ambient temperature	-30 ... 90 °C
Product weight according to length	0.037 kg/m
Colour	blue
Shore hardness	A 68 +/-3 D 53 +/-3
Materials note	Conforms to RoHS
Materials information for tubing	Polyamide 12 PVC-P